

Designed to isolate vehicle air systems in case of leakage

Protects the integrity of the air supply

Convenient in tank mounting

Variety of closing pressure options to suit application

Technical data

Operating pressure:

0 to 150 psi

0 to 10 bar

Material:

Zamak 3


Operating temperature:

-40°F to +200°F max.

-40°C to +93°C max.



Dimensions (Inches)

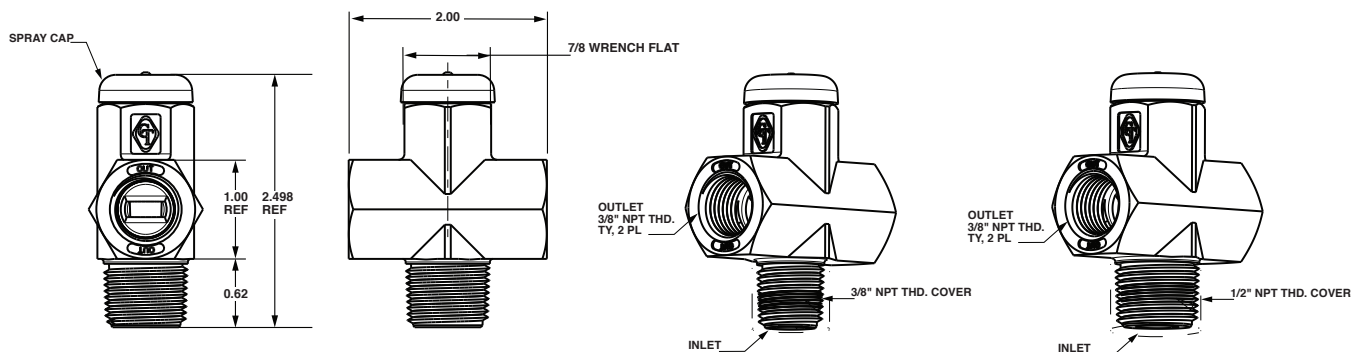

Models

Model		Open Pressure (psi)	Close Pressure (psi)	Thread
223-355V	●	55	45	3/8" NPT
223-365	●	65	55	3/8" NPT
223-385V	●	85	67	3/8" NPT
223-455V	●	55	45	1/2" PTF
223-485V	●	85	67	1/2" PTF
223-565	●	65	55	1/2" PTF
223-585-2	●	100	70	1/2" PTF