

3-way air valve

Designed for dashboard operation of truck air system accessories

Engineered for functionality and durability

Integral Push-to-Connect fittings (PTC)

Material used meets DOT FMVSS

302 flammability requirements

**Technical data****Operating pressure:**

0 to 150 psi (0 to 10 bar)

Operating temperature:

-20°F to +160°F (-20°C to +70°C)

Material:

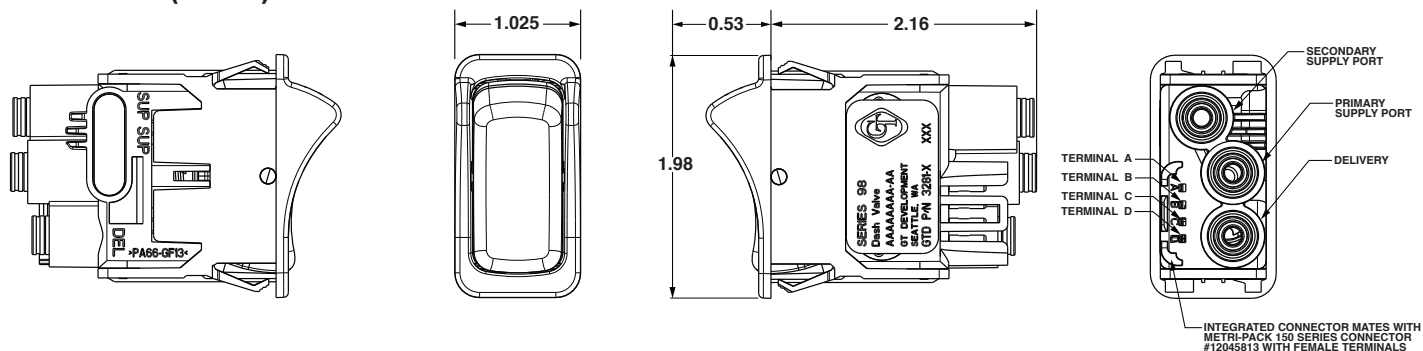
Nylon, glass filled



 
Tube O/D:




1/4"

Status lighting:

Red LED oval only

Dimensions (Inches)**Models**

Model	Description	Rocker Symbol	Rocker Text
3281-1	Inter-axle differential lock		Inter Axle
3281-2	5th wheel slide		5th Wheel
3281-3	Air suspension dump		SUSP Height

Model	Description	Rocker Symbol	Rocker Text
3281-4	Power take off		P.T.O.
3281-5	Air intake routing		Air Intake
3281-6	Neutral control		Neutral Control