

Check Valves

- » Widely used by leading truck manufacturers around the world today, IMI Norgren check valves are designed for strength and durability
- » Single and double check valves are available, with multiple port sizes
- » Incorporating standard IMI Norgren check valve components and proven technology

Technical Data

Medium:

Compressed air

Operating pressure:

0 to 250*psig

-40°F to 212°F

*Depending on tubing limitations.



Models - Single Check Valves

Model	Port 1	Port 2	Port 3
95403701M	1/2" PIF	1/2" NPTF	-


Models - Double Check Valves

Model	Port 1	Port 2	Port 3
AI04000404074	1/4" PIF	1/4" PIF	1/4" PIF
AI06000606074	3/8" PIF	3/8" PIF	3/8" PIF
AI06000648473	3/8" PIF	3/8" PIF	1/2" PIF
AI38000404474	1/4" PIF	3/8" NPT	1/4" PIF

Specifications


Single Check Valves

95403701M

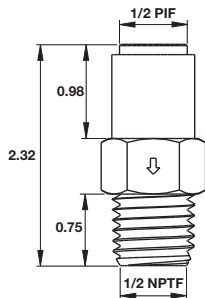


Double Check Valves


AI04000404074

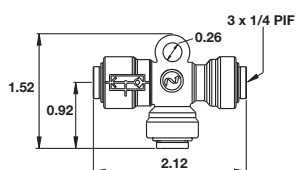

AI06000606074

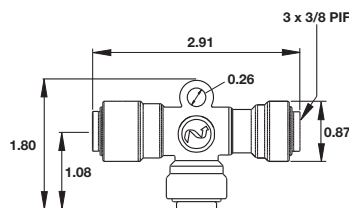

AI06000648473

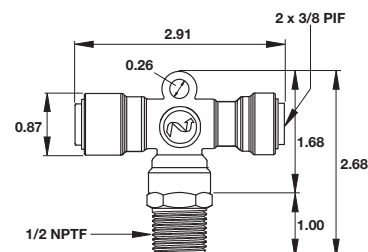

AI38000404474

