

NFPA A-SERIES ALUMINUM CYLINDERS

1-1/2" to 4" bore size

- Impact dampening seals
- Magnetic piston standard
- Adjustable captive cushion needle
- Ecology cylinders meet OSHA noise standards
- Constructed of the finest materials



TECHNICAL DATA

Medium:

Filtered compressed air to 250 PSI

Operating temperature:

-20°F to 200°F

Operating Pressure:

250 psig

Bore Sizes:

1-1/2", 2", 2-1/2", 3-1/4", 4"

Lubrication:

None required

Materials

Head and End Caps: Black anodized aluminum alloy

Tube: 1-1/2" to 4", Aluminum alloy, clear anodized O.D., hard coat anodized I.D..

Piston: Machined high-strength aluminum alloy.

Piston rod: hard chrome plated steel

Rod Bearing: oil impregnated sintered iron

Seals: Urethane rod seal/ wiper, nitrile piston seals, nitrile tube end seals

Tie Rods: high-tensile strength steel

Accessories

Bore	Rod eye	Rod clevis	Eye bracket	Rod alignment coupler
1-1/2"	49015A ●	49028A ●	49021 ●	CC-1-07 ●
2"	49015A ●	49028A ●	49021 ●	CC-1-07 ●
2-1/2"	49015A ●	49028A ●	49021 ●	CC-1-07 ●
3-1/4"	49013A ●	49030A ●	49020 ●	CC-1-12 ●
4"	49013A ●	49030A ●	49020 ●	CC-1-12 ●

Switches*

Bore	Model	Type	Bore	Model	Type
3/4" - 2-1/2"	CS8-2-04 ●	Reed	2" - 4"	CS7-04 ●	Reed
3/4" - 2-1/2"	CS8-2-31 ●	Solid state	2" - 4"	CS7-31 ●	Solid state
3/4" - 2-1/2"	CS8-2-32 ●	Solid state	2" - 4"	CS7-32 ●	Solid state


* See page ACT-64 for additional details.

Dimensions in inches

Bore	1-1/2"	2"	2-1/2"	3-1/4"	4"
ø Rod	5/8"	5/8"	5/8"	1"	1"
A	.750	.750	.750	1.125	1.125
C	.375	.375	.375	.500	.500
D	.500	.500	.500	.813	.813
E	2.000	2.500	3.000	3.750	4.500
EE	.375	.375	.375	.500	.500
G	1.500	1.500	1.500	1.750	1.750
J	1.000	1.000	1.000	1.250	1.250
K	.250	.313	.313	.375	.375
KK	7/16 - 20	7/16 - 20	7/16 - 20	3/4 - 16	3/4 - 16
LB	3.625	3.625	3.750	4.250	4.250
P	2.340	2.340	2.470	2.690	2.690
R	1.428	1.838	2.192	2.758	3.323
VF	.625	.625	.625	.875	.875
Y	1.840	1.840	1.840	2.380	2.380
ZB	4.875	4.938	5.063	6.000	6.000

● In stock

◆ Ships within one week


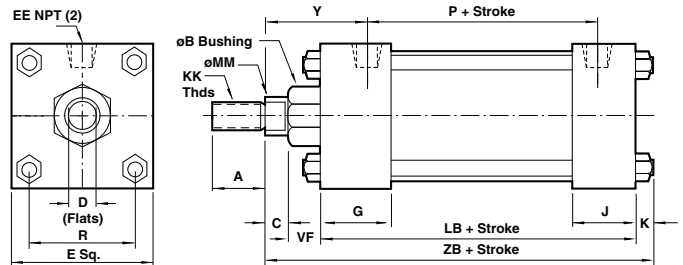


NFPA A-SERIES ALUMINUM CYLINDERS 1-1/2" to 4" bore size

Side Tapped (MS4) Non-cushioned

Dimensions in inches

Bore	1-1/2"	2"	2-1/2"	3-1/4"	4"
ND	0.375	0.375	0.5	0.75	0.75
NT	1/4-20	5/16-18	3/8-16	1/2-13	1/2-13
SN	2.25	2.25	2.375	2.625	2.625
TN	0.625	0.875	1.25	1.5	2.063
XT	1.938	1.938	1.938	2.438	2.438

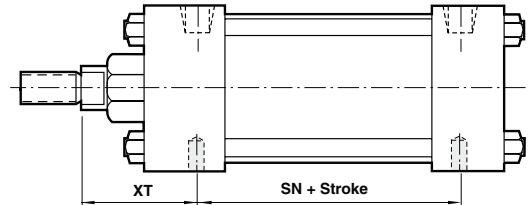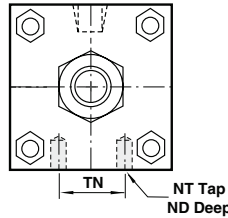

Models

Model Number	Cylinder Bore Ø	Stroke inches	Port Size NPT
--------------	-----------------	---------------	---------------

Accessories

Straight fitting	90° Swivel Elbow fitting	Banjo Flow Control	Tube O.D.	Rod Bearing kit	Service kit
------------------	--------------------------	--------------------	-----------	-----------------	-------------



A0133A1-PS 1-1/2 x 1	●	1-1/2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A0133A1-PS 1-1/2 x 2	●	1-1/2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A0133A1-PS 1-1/2 x 3	●	1-1/2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A0133A1-PS 1-1/2 x 4	●	1-1/2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A0133A1-PS 1-1/2 x 5	●	1-1/2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A0133A1-PS 1-1/2 x 6	●	1-1/2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A0133A1-PS 1-1/2 x 8	●	1-1/2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A0133A1-PS 1-1/2 x 10	●	1-1/2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A0133A1-PS 1-1/2 x 12	●	1-1/2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A0133A1-PS 2 x 1	●	2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A0133A1-PS 2 x 2	●	2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A0133A1-PS 2 x 3	●	2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A0133A1-PS 2 x 4	●	2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A0133A1-PS 2 x 5	●	2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A0133A1-PS 2 x 6	●	2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A0133A1-PS 2 x 8	●	2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A0133A1-PS 2 x 10	●	2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A0133A1-PS 2 x 12	●	2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A0133A1-PS 2-1/2 x 1	●	2-1/2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A0133A1-PS 2-1/2 x 2	●	2-1/2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A0133A1-PS 2-1/2 x 3	●	2-1/2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A0133A1-PS 2-1/2 x 4	●	2-1/2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A0133A1-PS 2-1/2 x 5	●	2-1/2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A0133A1-PS 2-1/2 x 6	●	2-1/2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A0133A1-PS 2-1/2 x 8	●	2-1/2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A0133A1-PS 2-1/2 x 10	●	2-1/2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A0133A1-PS 2-1/2 x 12	●	2-1/2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A0133B1-PS 3-1/4 x 1	●	3-1/4	1	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A0133B1-PS 3-1/4 x 2	●	3-1/4	2	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A0133B1-PS 3-1/4 x 3	●	3-1/4	3	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A0133B1-PS 3-1/4 x 4	●	3-1/4	4	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A0133B1-PS 3-1/4 x 5	●	3-1/4	5	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A0133B1-PS 3-1/4 x 6	●	3-1/4	6	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A0133B1-PS 3-1/4 x 8	●	3-1/4	8	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A0133B1-PS 3-1/4 x 10	●	3-1/4	10	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A0133B1-PS 3-1/4 x 12	●	3-1/4	12	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A0133B1-PS 4 x 1	●	4	1	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A0133B1-PS 4 x 2	●	4	2	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A0133B1-PS 4 x 3	●	4	3	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A0133B1-PS 4 x 4	●	4	4	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A0133B1-PS 4 x 5	●	4	5	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A0133B1-PS 4 x 6	●	4	6	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A0133B1-PS 4 x 8	●	4	8	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A0133B1-PS 4 x 10	●	4	10	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A0133B1-PS 4 x 12	●	4	12	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403

● In stock
◆ Ships within one week

1.800.514.0129

AVAILABILITY – SPEED – EXPERTISE
Order at: norgrenexpress.com Email: expressus@norgren.com

ACT-07



NFPA A-SERIES ALUMINUM CYLINDERS

1-1/2" to 4" bore size

Side Tapped (MS4) Adjustable Cushions

Dimensions in inches

Bore	1-1/2"	2"	2-1/2"	3-1/4"	4"
ND	0.375	0.375	0.5	0.75	0.75
NT	1/4-20	5/16-18	3/8-16	1/2-13	1/2-13
SN	2.25	2.25	2.375	2.625	2.625
TN	0.625	0.875	1.25	1.5	2.063
XT	1.938	1.938	1.938	2.438	2.438

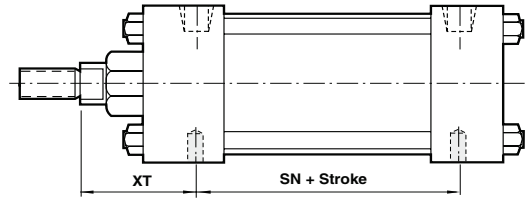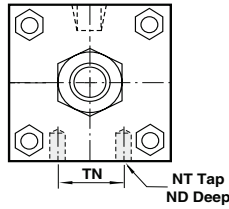

ACTUATORS

1

Models

Accessories

Model Number	Cylinder bore Ø	Stroke inches	Port size NPT	Straight fitting	90° Swivel Elbow	Banjo Flow Control	Tube O.D.	Rod bearing kit	Piston seal kit	Cushion seal kit
--------------	-----------------	---------------	---------------	------------------	------------------	--------------------	-----------	-----------------	-----------------	------------------



A0177A1-PS 1-1/2 x 1	●	1-1/2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A0177A1-PS 1-1/2 x 2	●	1-1/2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A0177A1-PS 1-1/2 x 3	●	1-1/2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A0177A1-PS 1-1/2 x 4	●	1-1/2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A0177A1-PS 1-1/2 x 5	●	1-1/2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A0177A1-PS 1-1/2 x 6	●	1-1/2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A0177A1-PS 1-1/2 x 8	●	1-1/2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A0177A1-PS 1-1/2 x 10	●	1-1/2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A0177A1-PS 1-1/2 x 12	●	1-1/2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A0177A1-PS 2 x 1	●	2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A0177A1-PS 2 x 2	●	2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A0177A1-PS 2 x 3	●	2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A0177A1-PS 2 x 4	●	2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A0177A1-PS 2 x 5	●	2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A0177A1-PS 2 x 6	●	2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A0177A1-PS 2 x 8	●	2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A0177A1-PS 2 x 10	●	2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A0177A1-PS 2 x 12	●	2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A0177A1-PS 2-1/2 x 1	●	2-1/2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A0177A1-PS 2-1/2 x 2	●	2-1/2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A0177A1-PS 2-1/2 x 3	●	2-1/2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A0177A1-PS 2-1/2 x 4	●	2-1/2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A0177A1-PS 2-1/2 x 5	●	2-1/2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A0177A1-PS 2-1/2 x 6	●	2-1/2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A0177A1-PS 2-1/2 x 8	●	2-1/2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A0177A1-PS 2-1/2 x 10	●	2-1/2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A0177A1-PS 2-1/2 x 12	●	2-1/2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A0177B1-PS 3-1/4 x 1	●	3-1/4	1	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A0177B1-PS 3-1/4 x 2	●	3-1/4	2	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A0177B1-PS 3-1/4 x 3	●	3-1/4	3	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A0177B1-PS 3-1/4 x 4	●	3-1/4	4	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A0177B1-PS 3-1/4 x 5	●	3-1/4	5	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A0177B1-PS 3-1/4 x 6	●	3-1/4	6	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A0177B1-PS 3-1/4 x 8	●	3-1/4	8	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A0177B1-PS 3-1/4 x 10	●	3-1/4	10	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A0177B1-PS 3-1/4 x 12	●	3-1/4	12	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A0177B1-PS 4 x 1	●	4	1	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A0177B1-PS 4 x 2	●	4	2	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A0177B1-PS 4 x 3	●	4	3	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A0177B1-PS 4 x 4	●	4	4	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A0177B1-PS 4 x 5	●	4	5	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A0177B1-PS 4 x 6	●	4	6	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A0177B1-PS 4 x 8	●	4	8	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A0177B1-PS 4 x 10	●	4	10	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A0177B1-PS 4 x 12	●	4	12	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23



NFPA A-SERIES ALUMINUM CYLINDERS

1-1/2" to 4" bore size

Side Tapped (MS4) With Impact Dampening Ecology Seals, fixed cushion

Dimensions in inches

Bore	1-1/2"	2"	2-1/2"	3-1/4"	4"
ND	0.375	0.375	0.5	0.75	0.75
NT	1/4-20	5/16-18	3/8-16	1/2-13	1/2-13
SN	2.25	2.25	2.375	2.625	2.625
TN	0.625	0.875	1.25	1.5	2.063
XT	1.938	1.938	1.938	2.438	2.438

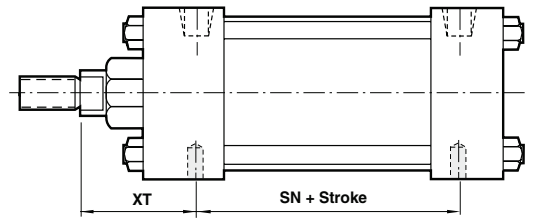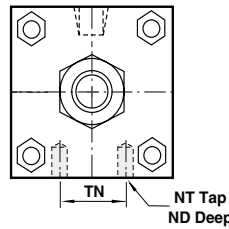

Models

Model Number	Cylinder bore Ø	Stroke inches	Port size NPT
--------------	-----------------	---------------	---------------

Accessories

Straight fitting	90° Swivel Elbow	Banjo Flow Control	Tube O.D.	Rod bearing kit	Piston seal kit	Cushion seal kit
------------------	------------------	--------------------	-----------	-----------------	-----------------	------------------



EA0155A1-PS 1-1/2 x 1	●	1-1/2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA0155A1-PS 1-1/2 x 2	●	1-1/2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA0155A1-PS 1-1/2 x 3	●	1-1/2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA0155A1-PS 1-1/2 x 4	●	1-1/2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA0155A1-PS 1-1/2 x 5	●	1-1/2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA0155A1-PS 1-1/2 x 6	●	1-1/2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA0155A1-PS 1-1/2 x 8	●	1-1/2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA0155A1-PS 1-1/2 x 10	●	1-1/2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA0155A1-PS 1-1/2 x 12	●	1-1/2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA0155A1-PS 2 x 1	●	2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA0155A1-PS 2 x 2	●	2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA0155A1-PS 2 x 3	●	2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA0155A1-PS 2 x 4	●	2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA0155A1-PS 2 x 5	●	2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA0155A1-PS 2 x 6	●	2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA0155A1-PS 2 x 8	●	2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA0155A1-PS 2 x 10	●	2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA0155A1-PS 2 x 12	●	2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA0155A1-PS 2-1/2 x 1	●	2-1/2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA0155A1-PS 2-1/2 x 2	●	2-1/2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA0155A1-PS 2-1/2 x 3	●	2-1/2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA0155A1-PS 2-1/2 x 4	●	2-1/2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA0155A1-PS 2-1/2 x 5	●	2-1/2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA0155A1-PS 2-1/2 x 6	●	2-1/2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA0155A1-PS 2-1/2 x 8	●	2-1/2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA0155A1-PS 2-1/2 x 10	●	2-1/2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA0155A1-PS 2-1/2 x 12	●	2-1/2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA0155B1-PS 3-1/4 x 1	●	3-1/4	1	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA0155B1-PS 3-1/4 x 2	●	3-1/4	2	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA0155B1-PS 3-1/4 x 3	●	3-1/4	3	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA0155B1-PS 3-1/4 x 4	●	3-1/4	4	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA0155B1-PS 3-1/4 x 5	●	3-1/4	5	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA0155B1-PS 3-1/4 x 6	●	3-1/4	6	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA0155B1-PS 3-1/4 x 8	●	3-1/4	8	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA0155B1-PS 3-1/4 x 10	●	3-1/4	10	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA0155B1-PS 3-1/4 x 12	●	3-1/4	12	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA0155B1-PS 4 x 1	●	4	1	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA0155B1-PS 4 x 2	●	4	2	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA0155B1-PS 4 x 3	●	4	3	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA0155B1-PS 4 x 4	●	4	4	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA0155B1-PS 4 x 5	●	4	5	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA0155B1-PS 4 x 6	●	4	6	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA0155B1-PS 4 x 8	●	4	8	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA0155B1-PS 4 x 10	●	4	10	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA0155B1-PS 4 x 12	●	4	12	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23

- In stock
- ◆ Ships within one week


NFPA A-SERIES ALUMINUM CYLINDERS

1-1/2" to 4" bore size

Front Flange (MF1) Non-cushioned

Dimensions in inches

Bore	1-1/2"	2"	2-1/2"	3-1/4"	4"
E	2	2.5	3	3.75	4.5
F	0.375	0.375	0.375	0.625	0.625
FB	0.313	0.375	0.375	0.438	0.438
R	1.428	1.838	2.192	2.758	3.323
TF	2.75	3.375	3.875	4.688	5.438
UF	3.375	4.125	4.625	5.5	6.25
W	0.625	0.625	0.625	0.75	0.75

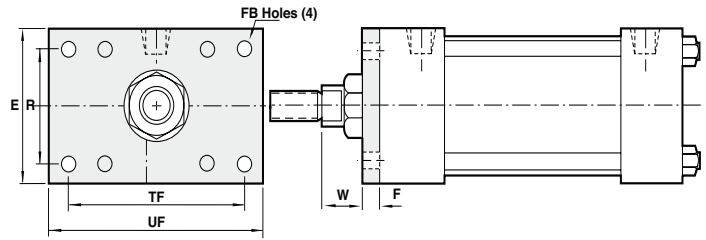







ACTUATORS

1

Models

Accessories

Model Number	Cylinder Bore Ø	Stroke inches	Port Size NPT	Straight fitting	90° Swivel Elbow fitting	Banjo Flow Control	Tube O.D.	Rod bearing kit	Piston seal kit
									
A0333A1-PS 1-1/2 x 1	● 1-1/2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A0333A1-PS 1-1/2 x 2	● 1-1/2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A0333A1-PS 1-1/2 x 3	● 1-1/2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A0333A1-PS 1-1/2 x 4	● 1-1/2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A0333A1-PS 1-1/2 x 5	● 1-1/2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A0333A1-PS 1-1/2 x 6	● 1-1/2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A0333A1-PS 1-1/2 x 8	● 1-1/2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A0333A1-PS 1-1/2 x 10	● 1-1/2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A0333A1-PS 1-1/2 x 12	● 1-1/2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A0333A1-PS 2 x 1	● 2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A0333A1-PS 2 x 2	● 2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A0333A1-PS 2 x 3	● 2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A0333A1-PS 2 x 4	● 2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A0333A1-PS 2 x 5	● 2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A0333A1-PS 2 x 6	● 2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A0333A1-PS 2 x 8	● 2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A0333A1-PS 2 x 10	● 2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A0333A1-PS 2 x 12	● 2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A0333A1-PS 2-1/2 x 1	● 2-1/2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A0333A1-PS 2-1/2 x 2	● 2-1/2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A0333A1-PS 2-1/2 x 3	● 2-1/2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A0333A1-PS 2-1/2 x 4	● 2-1/2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A0333A1-PS 2-1/2 x 5	● 2-1/2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A0333A1-PS 2-1/2 x 6	● 2-1/2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A0333A1-PS 2-1/2 x 8	● 2-1/2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A0333A1-PS 2-1/2 x 10	● 2-1/2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A0333A1-PS 2-1/2 x 12	● 2-1/2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A0333B1-PS 3-1/4 x 1	● 3-1/4	1	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A0333B1-PS 3-1/4 x 2	● 3-1/4	2	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A0333B1-PS 3-1/4 x 3	● 3-1/4	3	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A0333B1-PS 3-1/4 x 4	● 3-1/4	4	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A0333B1-PS 3-1/4 x 5	● 3-1/4	5	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A0333B1-PS 3-1/4 x 6	● 3-1/4	6	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A0333B1-PS 3-1/4 x 8	● 3-1/4	8	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A0333B1-PS 3-1/4 x 10	● 3-1/4	10	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A0333B1-PS 3-1/4 x 12	● 3-1/4	12	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A0333B1-PS 4 x 1	● 4	1	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A0333B1-PS 4 x 2	● 4	2	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A0333B1-PS 4 x 3	● 4	3	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A0333B1-PS 4 x 4	● 4	4	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A0333B1-PS 4 x 5	● 4	5	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A0333B1-PS 4 x 6	● 4	6	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A0333B1-PS 4 x 8	● 4	8	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A0333B1-PS 4 x 10	● 4	10	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A0333B1-PS 4 x 12	● 4	12	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403


● In stock
◆ Ships within one week

NFPA A-SERIES ALUMINUM CYLINDERS 1-1/2" to 4" bore size


Front Flange Mount (MF1) Adjustable Cushions

Dimensions in inches

Bore	1-1/2"	2"	2-1/2"	3-1/4"	4"
E	2	2.5	3	3.75	4.5
F	0.375	0.375	0.375	0.625	0.625
FB	0.313	0.375	0.375	0.438	0.438
R	1.428	1.838	2.192	2.758	3.323
TF	2.75	3.375	3.875	4.688	5.438
UF	3.375	4.125	4.625	5.5	6.25
W	0.625	0.625	0.625	0.75	0.75

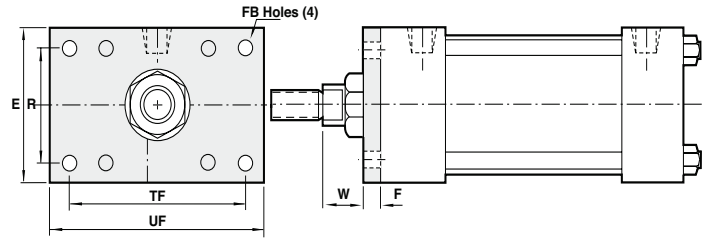

Models

Model Number	Cylinder bore Ø	Stroke inches	Port size NPT	Straight fitting	90° Swivel Elbow	Banjo Flow Control	Tube O.D.	Rod bearing kit	Piston seal kit	Cushion seal kit
 A0377A1-PS 1-1/2 x 1	● 1-1/2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A0377A1-PS 1-1/2 x 2	● 1-1/2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A0377A1-PS 1-1/2 x 3	● 1-1/2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A0377A1-PS 1-1/2 x 4	● 1-1/2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A0377A1-PS 1-1/2 x 5	● 1-1/2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A0377A1-PS 1-1/2 x 6	● 1-1/2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A0377A1-PS 1-1/2 x 8	● 1-1/2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A0377A1-PS 1-1/2 x 10	● 1-1/2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A0377A1-PS 1-1/2 x 12	● 1-1/2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A0377A1-PS 2 x 1	● 2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A0377A1-PS 2 x 2	● 2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A0377A1-PS 2 x 3	● 2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A0377A1-PS 2 x 4	● 2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A0377A1-PS 2 x 5	● 2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A0377A1-PS 2 x 6	● 2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A0377A1-PS 2 x 8	● 2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A0377A1-PS 2 x 10	● 2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A0377A1-PS 2 x 12	● 2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A0377A1-PS 2-1/2 x 1	● 2-1/2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A0377A1-PS 2-1/2 x 2	● 2-1/2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A0377A1-PS 2-1/2 x 3	● 2-1/2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A0377A1-PS 2-1/2 x 4	● 2-1/2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A0377A1-PS 2-1/2 x 5	● 2-1/2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A0377A1-PS 2-1/2 x 6	● 2-1/2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A0377A1-PS 2-1/2 x 8	● 2-1/2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A0377A1-PS 2-1/2 x 10	● 2-1/2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A0377A1-PS 2-1/2 x 12	● 2-1/2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A0377B1-PS 3-1/4 x 1	● 3-1/4	1	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A0377B1-PS 3-1/4 x 2	● 3-1/4	2	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A0377B1-PS 3-1/4 x 3	● 3-1/4	3	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A0377B1-PS 3-1/4 x 4	● 3-1/4	4	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A0377B1-PS 3-1/4 x 5	● 3-1/4	5	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A0377B1-PS 3-1/4 x 6	● 3-1/4	6	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A0377B1-PS 3-1/4 x 8	● 3-1/4	8	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A0377B1-PS 3-1/4 x 10	● 3-1/4	10	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A0377B1-PS 3-1/4 x 12	● 3-1/4	12	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A0377B1-PS 4 x 1	● 4	1	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A0377B1-PS 4 x 2	● 4	2	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A0377B1-PS 4 x 3	● 4	3	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A0377B1-PS 4 x 4	● 4	4	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A0377B1-PS 4 x 5	● 4	5	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A0377B1-PS 4 x 6	● 4	6	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A0377B1-PS 4 x 8	● 4	8	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A0377B1-PS 4 x 10	● 4	10	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A0377B1-PS 4 x 12	● 4	12	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23

- In stock
- ◆ Ships within one week


NFPA A-SERIES ALUMINUM CYLINDERS

1-1/2" to 4" bore size

Front Flange Mount (MF1) With Impact Dampening Ecology Seals and fixed cushion

Dimensions in inches

Bore	1-1/2"	2"	2-1/2"	3-1/4"	4"
E	2	2.5	3	3.75	4.5
F	0.375	0.375	0.375	0.625	0.625
FB	0.313	0.375	0.375	0.438	0.438
R	1.428	1.838	2.192	2.758	3.323
TF	2.75	3.375	3.875	4.688	5.438
UF	3.375	4.125	4.625	5.5	6.25
W	0.625	0.625	0.625	0.75	0.75

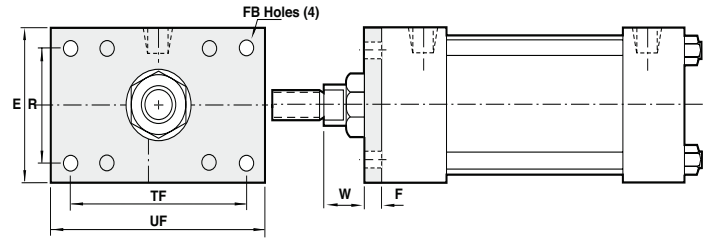

ACTUATORS

1

Models

Model Number	Cylinder bore Ø	Stroke inches	Port size NPT	Straight fitting	90° Swivel Elbow	Banjo Flow Control	Tube O.D.	Rod bearing kit	Piston seal kit	Cushion seal kit
--------------	-----------------	---------------	---------------	------------------	------------------	--------------------	-----------	-----------------	-----------------	------------------



EA0355A1-PS 1-1/2 x 1	●	1-1/2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA0355A1-PS 1-1/2 x 2	●	1-1/2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA0355A1-PS 1-1/2 x 3	●	1-1/2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA0355A1-PS 1-1/2 x 4	●	1-1/2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA0355A1-PS 1-1/2 x 5	●	1-1/2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA0355A1-PS 1-1/2 x 6	●	1-1/2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA0355A1-PS 1-1/2 x 8	●	1-1/2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA0355A1-PS 1-1/2 x 10	●	1-1/2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA0355A1-PS 1-1/2 x 12	●	1-1/2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA0355A1-PS 2 x 1	●	2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA0355A1-PS 2 x 2	●	2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA0355A1-PS 2 x 3	●	2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA0355A1-PS 2 x 4	●	2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA0355A1-PS 2 x 5	●	2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA0355A1-PS 2 x 6	●	2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA0355A1-PS 2 x 8	●	2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA0355A1-PS 2 x 10	●	2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA0355A1-PS 2 x 12	●	2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA0355A1-PS 2-1/2 x 1	●	2-1/2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA0355A1-PS 2-1/2 x 2	●	2-1/2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA0355A1-PS 2-1/2 x 3	●	2-1/2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA0355A1-PS 2-1/2 x 4	●	2-1/2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA0355A1-PS 2-1/2 x 5	●	2-1/2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA0355A1-PS 2-1/2 x 6	●	2-1/2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA0355A1-PS 2-1/2 x 8	●	2-1/2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA0355A1-PS 2-1/2 x 10	●	2-1/2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA0355A1-PS 2-1/2 x 12	●	2-1/2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA0355B1-PS 3-1/4 x 1	●	3-1/4	1	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA0355B1-PS 3-1/4 x 2	●	3-1/4	2	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA0355B1-PS 3-1/4 x 3	●	3-1/4	3	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA0355B1-PS 3-1/4 x 4	●	3-1/4	4	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA0355B1-PS 3-1/4 x 5	●	3-1/4	5	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA0355B1-PS 3-1/4 x 6	●	3-1/4	6	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA0355B1-PS 3-1/4 x 8	●	3-1/4	8	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA0355B1-PS 3-1/4 x 10	●	3-1/4	10	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA0355B1-PS 3-1/4 x 12	●	3-1/4	12	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA0355B1-PS 4 x 1	●	4	1	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA0355B1-PS 4 x 2	●	4	2	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA0355B1-PS 4 x 3	●	4	3	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA0355B1-PS 4 x 4	●	4	4	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA0355B1-PS 4 x 5	●	4	5	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA0355B1-PS 4 x 6	●	4	6	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA0355B1-PS 4 x 8	●	4	8	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA0355B1-PS 4 x 10	●	4	10	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA0355B1-PS 4 x 12	●	4	12	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23

● In stock
◆ Ships within one week


NFPA A-SERIES ALUMINUM CYLINDERS

1-1/2" to 4" bore size

Fixed Cap Clevis Mount (MP1) Non-cushioned

Dimensions in inches

Bore	1-1/2"	2"	2-1/2"	3-1/4"	4"
CB	0.75	0.75	0.75	1.25	1.25
CD	0.5	0.5	0.5	0.75	0.75
CW	0.5	0.5	0.5	0.625	0.625
L	0.75	0.75	0.75	1.25	1.25
LB	3.625	3.625	3.75	4.25	4.25
LR	0.75	0.75	0.75	1.25	1.25
MR	0.625	0.625	0.625	0.938	0.938
XC	5.375	5.375	5.5	6.875	6.875

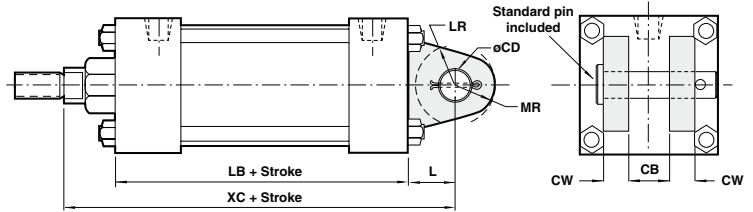

Models

Model Number	Cylinder Bore Ø	Stroke inches	Port Size NPT
--------------	-----------------	---------------	---------------

Accessories

Straight fitting	90° Swivel Elbow fitting	Banjo Flow Control	Tube O.D.	Rod bearing kit	Piston seal kit
------------------	--------------------------	--------------------	-----------	-----------------	-----------------



A1233A1-PS 1-1/2 x 1	●	1-1/2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A1233A1-PS 1-1/2 x 2	●	1-1/2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A1233A1-PS 1-1/2 x 3	●	1-1/2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A1233A1-PS 1-1/2 x 4	●	1-1/2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A1233A1-PS 1-1/2 x 5	●	1-1/2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A1233A1-PS 1-1/2 x 6	●	1-1/2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A1233A1-PS 1-1/2 x 8	●	1-1/2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A1233A1-PS 1-1/2 x 10	●	1-1/2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A1233A1-PS 1-1/2 x 12	●	1-1/2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153
A1233A1-PS 2 x 1	●	2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A1233A1-PS 2 x 2	●	2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A1233A1-PS 2 x 3	●	2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A1233A1-PS 2 x 4	●	2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A1233A1-PS 2 x 5	●	2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A1233A1-PS 2 x 6	●	2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A1233A1-PS 2 x 8	●	2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A1233A1-PS 2 x 10	●	2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A1233A1-PS 2 x 12	●	2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203
A1233A1-PS 2-1/2 x 1	●	2-1/2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A1233A1-PS 2-1/2 x 2	●	2-1/2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A1233A1-PS 2-1/2 x 3	●	2-1/2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A1233A1-PS 2-1/2 x 4	●	2-1/2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A1233A1-PS 2-1/2 x 5	●	2-1/2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A1233A1-PS 2-1/2 x 6	●	2-1/2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A1233A1-PS 2-1/2 x 8	●	2-1/2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A1233A1-PS 2-1/2 x 10	●	2-1/2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A1233A1-PS 2-1/2 x 12	●	2-1/2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253
A1233B1-PS 3-1/4 x 1	●	3-1/4	1	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A1233B1-PS 3-1/4 x 2	●	3-1/4	2	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A1233B1-PS 3-1/4 x 3	●	3-1/4	3	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A1233B1-PS 3-1/4 x 4	●	3-1/4	4	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A1233B1-PS 3-1/4 x 5	●	3-1/4	5	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A1233B1-PS 3-1/4 x 6	●	3-1/4	6	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A1233B1-PS 3-1/4 x 8	●	3-1/4	8	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A1233B1-PS 3-1/4 x 10	●	3-1/4	10	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A1233B1-PS 3-1/4 x 12	●	3-1/4	12	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323
A1233B1-PS 4 x 1	●	4	1	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A1233B1-PS 4 x 2	●	4	2	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A1233B1-PS 4 x 3	●	4	3	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A1233B1-PS 4 x 4	●	4	4	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A1233B1-PS 4 x 5	●	4	5	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A1233B1-PS 4 x 6	●	4	6	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A1233B1-PS 4 x 8	●	4	8	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A1233B1-PS 4 x 10	●	4	10	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403
A1233B1-PS 4 x 12	●	4	12	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403

NFPA A-SERIES ALUMINUM CYLINDERS


1-1/2" to 4" bore size

Fixed Cap Clevis Mount (MP1) Adjustable Cushions

ACTUATORS

Dimensions in inches

Bore	1-1/2"	2"	2-1/2"	3-1/4"	4"
CB	0.75	0.75	0.75	1.25	1.25
CD	0.5	0.5	0.5	0.75	0.75
CW	0.5	0.5	0.5	0.625	0.625
L	0.75	0.75	0.75	1.25	1.25
LB	3.625	3.625	3.75	4.25	4.25
LR	0.75	0.75	0.75	1.25	1.25
MR	0.625	0.625	0.625	0.938	0.938
XC	5.375	5.375	5.5	6.875	6.875

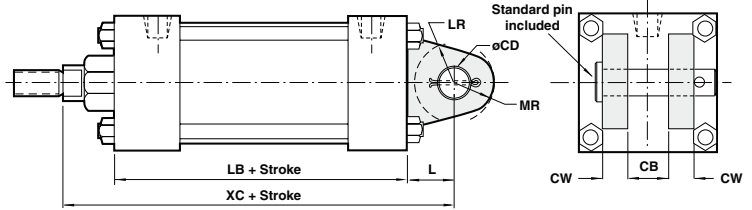

Models

Model Number	Cylinder bore ø	Stroke inches	Port size NPT	Straight fitting	90° Swivel Elbow	Banjo Flow Control	Tube O.D.	Rod bearing kit	Piston seal kit	Cushion seal kit
--------------	-----------------	---------------	---------------	------------------	------------------	--------------------	-----------	-----------------	-----------------	------------------




A1277A1-PS 1-1/2 x 1	●	1-1/2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A1277A1-PS 1-1/2 x 2	●	1-1/2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A1277A1-PS 1-1/2 x 3	●	1-1/2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A1277A1-PS 1-1/2 x 4	●	1-1/2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A1277A1-PS 1-1/2 x 5	●	1-1/2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A1277A1-PS 1-1/2 x 6	●	1-1/2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A1277A1-PS 1-1/2 x 8	●	1-1/2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A1277A1-PS 1-1/2 x 10	●	1-1/2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A1277A1-PS 1-1/2 x 12	●	1-1/2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-153	CSK-15-13
A1277A1-PS 2 x 1	●	2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A1277A1-PS 2 x 2	●	2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A1277A1-PS 2 x 3	●	2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A1277A1-PS 2 x 4	●	2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A1277A1-PS 2 x 5	●	2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A1277A1-PS 2 x 6	●	2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A1277A1-PS 2 x 8	●	2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A1277A1-PS 2 x 10	●	2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A1277A1-PS 2 x 12	●	2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-203	CSK-15-13
A1277A1-PS 2-1/2 x 1	●	2-1/2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A1277A1-PS 2-1/2 x 2	●	2-1/2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A1277A1-PS 2-1/2 x 3	●	2-1/2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A1277A1-PS 2-1/2 x 4	●	2-1/2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A1277A1-PS 2-1/2 x 5	●	2-1/2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A1277A1-PS 2-1/2 x 6	●	2-1/2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A1277A1-PS 2-1/2 x 8	●	2-1/2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A1277A1-PS 2-1/2 x 10	●	2-1/2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A1277A1-PS 2-1/2 x 12	●	2-1/2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	AJK-253	CSK-15-13
A1277B1-PS 3-1/4 x 1	●	3-1/4	1	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A1277B1-PS 3-1/4 x 2	●	3-1/4	2	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A1277B1-PS 3-1/4 x 3	●	3-1/4	3	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A1277B1-PS 3-1/4 x 4	●	3-1/4	4	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A1277B1-PS 3-1/4 x 5	●	3-1/4	5	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A1277B1-PS 3-1/4 x 6	●	3-1/4	6	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A1277B1-PS 3-1/4 x 8	●	3-1/4	8	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A1277B1-PS 3-1/4 x 10	●	3-1/4	10	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A1277B1-PS 3-1/4 x 12	●	3-1/4	12	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-323	CSK-25-23
A1277B1-PS 4 x 1	●	4	1	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A1277B1-PS 4 x 2	●	4	2	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A1277B1-PS 4 x 3	●	4	3	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A1277B1-PS 4 x 4	●	4	4	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A1277B1-PS 4 x 5	●	4	5	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A1277B1-PS 4 x 6	●	4	6	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A1277B1-PS 4 x 8	●	4	8	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A1277B1-PS 4 x 10	●	4	10	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23
A1277B1-PS 4 x 12	●	4	12	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	AJK-403	CSK-25-23

NFPA A-SERIES ALUMINUM CYLINDERS 1-1/2" to 4" bore size

Fixed Cap Clevis Mount (MP1) With Impact Dampening Ecology Seals and fixed cushion


Dimensions in inches

Bore	1-1/2"	2"	2-1/2"	3-1/4"	4"
CB	0.75	0.75	0.75	1.25	1.25
CD	0.5	0.5	0.5	0.75	0.75
CW	0.5	0.5	0.5	0.625	0.625
L	0.75	0.75	0.75	1.25	1.25
LB	3.625	3.625	3.75	4.25	4.25
LR	0.75	0.75	0.75	1.25	1.25
MR	0.625	0.625	0.625	0.938	0.938
XC	5.375	5.375	5.5	6.875	6.875

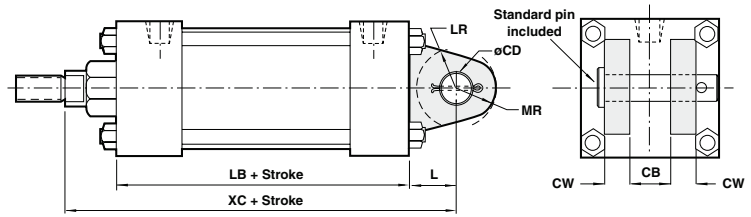

Models

Accessories

Model Number	Cylinder bore Ø	Stroke inches	Port size NPT	Straight fitting	90° Swivel Elbow	Banjo Flow Control	Tube O.D.	Rod bearing kit	Piston seal kit	Cushion seal kit
 EA1255A1-PS 1-1/2 x 1	● 1-1/2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA1255A1-PS 1-1/2 x 2	● 1-1/2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA1255A1-PS 1-1/2 x 3	● 1-1/2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA1255A1-PS 1-1/2 x 4	● 1-1/2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA1255A1-PS 1-1/2 x 5	● 1-1/2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA1255A1-PS 1-1/2 x 6	● 1-1/2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA1255A1-PS 1-1/2 x 8	● 1-1/2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA1255A1-PS 1-1/2 x 10	● 1-1/2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA1255A1-PS 1-1/2 x 12	● 1-1/2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-153	CSK-15-13
EA1255A1-PS 2 x 1	● 2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA1255A1-PS 2 x 2	● 2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA1255A1-PS 2 x 3	● 2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA1255A1-PS 2 x 4	● 2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA1255A1-PS 2 x 5	● 2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA1255A1-PS 2 x 6	● 2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA1255A1-PS 2 x 8	● 2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA1255A1-PS 2 x 10	● 2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA1255A1-PS 2 x 12	● 2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-203	CSK-15-13
EA1255A1-PS 2-1/2 x 1	● 2-1/2	1	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA1255A1-PS 2-1/2 x 2	● 2-1/2	2	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA1255A1-PS 2-1/2 x 3	● 2-1/2	3	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA1255A1-PS 2-1/2 x 4	● 2-1/2	4	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA1255A1-PS 2-1/2 x 5	● 2-1/2	5	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA1255A1-PS 2-1/2 x 6	● 2-1/2	6	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA1255A1-PS 2-1/2 x 8	● 2-1/2	8	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA1255A1-PS 2-1/2 x 10	● 2-1/2	10	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA1255A1-PS 2-1/2 x 12	● 2-1/2	12	3/8	C24250638	C24470638	C2VA00638	3/8	RBK-15	EJK-253	CSK-15-13
EA1255B1-PS 3-1/4 x 1	● 3-1/4	1	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA1255B1-PS 3-1/4 x 2	● 3-1/4	2	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA1255B1-PS 3-1/4 x 3	● 3-1/4	3	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA1255B1-PS 3-1/4 x 4	● 3-1/4	4	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA1255B1-PS 3-1/4 x 5	● 3-1/4	5	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA1255B1-PS 3-1/4 x 6	● 3-1/4	6	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA1255B1-PS 3-1/4 x 8	● 3-1/4	8	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA1255B1-PS 3-1/4 x 10	● 3-1/4	10	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA1255B1-PS 3-1/4 x 12	● 3-1/4	12	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-323	CSK-25-23
EA1255B1-PS 4 x 1	● 4	1	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA1255B1-PS 4 x 2	● 4	2	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA1255B1-PS 4 x 3	● 4	3	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA1255B1-PS 4 x 4	● 4	4	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA1255B1-PS 4 x 5	● 4	5	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA1255B1-PS 4 x 6	● 4	6	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA1255B1-PS 4 x 8	● 4	8	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA1255B1-PS 4 x 10	● 4	10	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23
EA1255B1-PS 4 x 12	● 4	12	1/2	C24250748	C24470748	C2VA00748	1/2	RBK-25	EJK-403	CSK-25-23