

Robust component parts for use on and around the engine

Designed for continuous duty in high temperature applications




Integral Push-To-Connect (PTC) fittings

Technical data




- Operating pressure:**
60 to 150 psi (5 to 10 bar)
- Operating temperature:**
-40°F- 257°F (-40°C- 125°C)
-40°F to 200°F (5030-310B)
- Operating voltage:**
9 to 16 volts

Dimensions (Inches)

5030-111

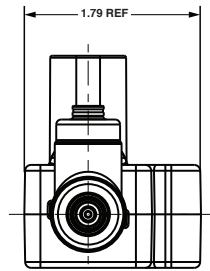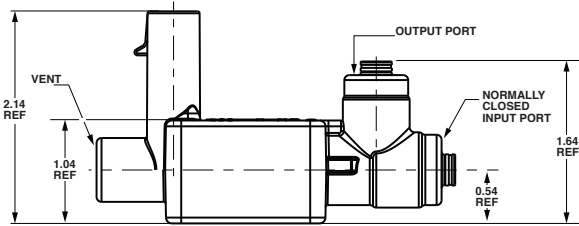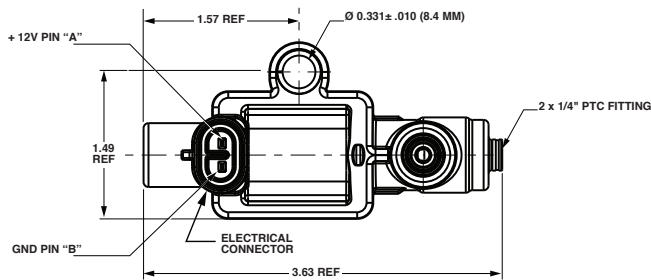


5030-211

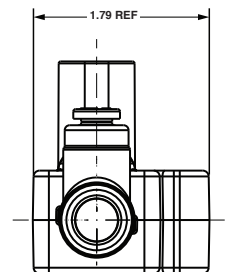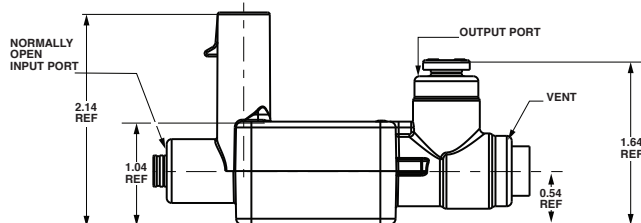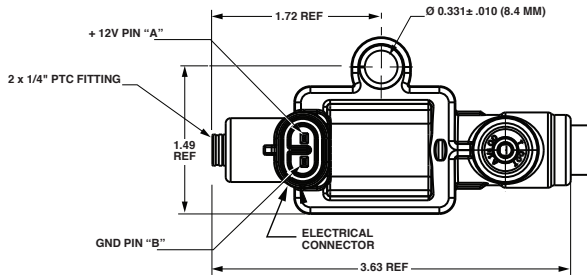

Dimensions (Inches)

5030-310B

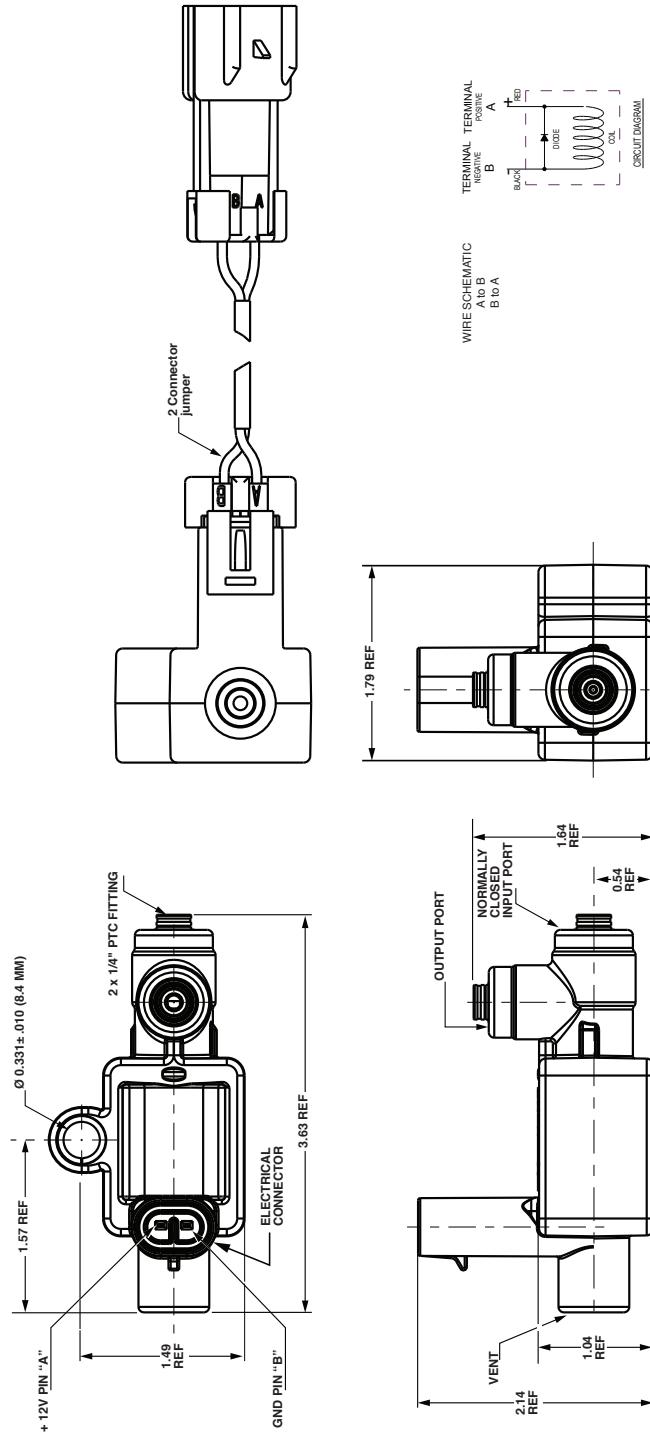

Models

Model	Description	O/D Tube
5030-111	● Three-way NC	1/4"
5030-211	● Three-way NO	1/4"
5030-310B	● Two-way NC	1/4"

- In stock
- ◆ Please call 1.800.710.7823 for availability