

Compact design

Filter has high efficiency water and particle removal

Push to lock adjusting knob with
tamper resistant option

Nearly constant oil density output with varying air flow

Use Micro-Fog models in applications
containing one or more points of lubrication.

Use Oil-Fog models to lubricate a single
tool, cylinder, or other air driven device.



C72A



C74A

Technical data

Refer to individual component
sections for product specifications

Ordering information

Models listed include PTF threads. Filter (F) includes automatic drain, metal bowl with level indicator, and a 40µm element. Regulator (R) is relieving type with knob adjustment, 150 psig (10 bar) regulating spring, and gauge. Lubricator (L) is a Micro-Fog model with 1/4 turn manual drain and metal bowl with level indicator.

Combination Unit Type	Port Size	Model**	Weight lb (kg)
Filter-Regulator-Lubricator	1/4"	C72A-2AK-AE3-RMG-QEB	3.23 (1.47)
	3/8"	C73A-3AK-AD3-RMG-QDB	4.36 (1.98)
	1/2"	C74A-4AK-AD3-RMG-QDB	6.04 (2.74)
	3/4"	C74A-6AK-AD3-RMG-QDB	5.91 (2.68)




** For oil fog lubricator use "B" in the 4th position.

Other combinations are available. Please consult Technical support for more information.

C72A-

C73A-

C74A-

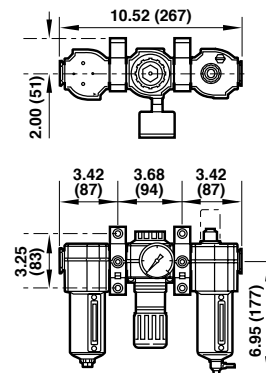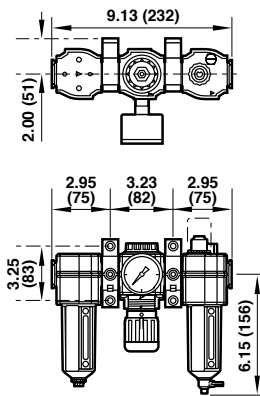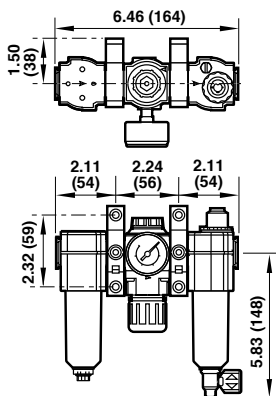

Dimensions in inches (mm).