

Standard Silencer



Nominal size 12 to 50
Dynamic pressure 6 bar
Connection external thread G 1/2 to G 2

Catalog Register
P 21

Publication 7501081.06.01.98




Description

Operating fluid: Air
Temperature range: -10 to +60 °C
Materials:
- Housing: Sheet steel, enamelled
- Perforated plate: Galvanized sheet steel
- Filter: Age-resistant polyester felt



Dimensional drawing

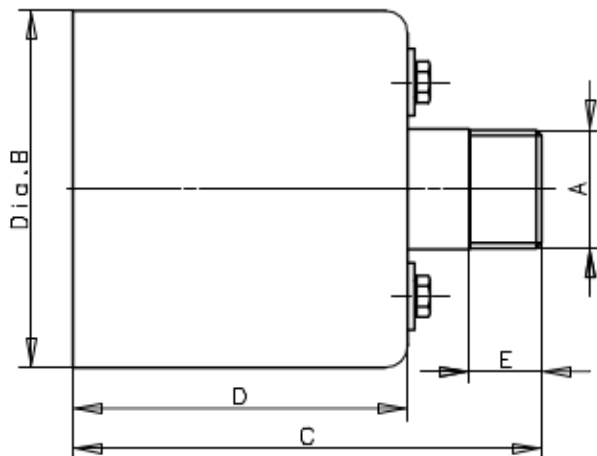

Dimensional table [mm]


A	Dia. B	C	D	E	Cat. No.
G 1/2	80	103	75	14	0016330
G 3/4	80	106	75	16	0016430
G 1	110	134	100	18	0016530
G 1 1/4	110	140	100	20	0011230
G 1 1/2	150	172	125	24	0016630
G 2	150	172	125	24	0016730

Diagrams for sound level and flow rate

———— Sound level
 - - - - - Flow Q


Silencer G 1/2

Cat. No. 0016330

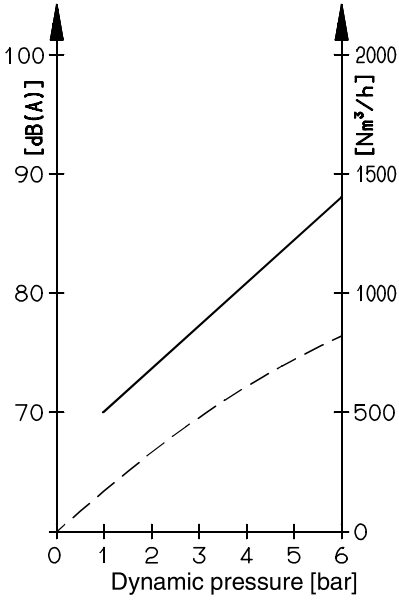


Silencer G 3/4

Cat. No. 0016430

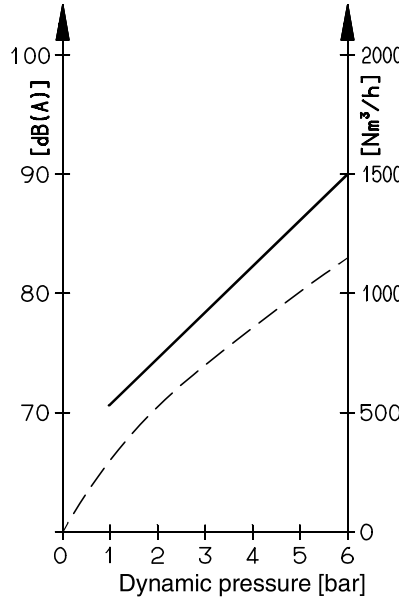


Silencer G 1

Cat. No. 0016530

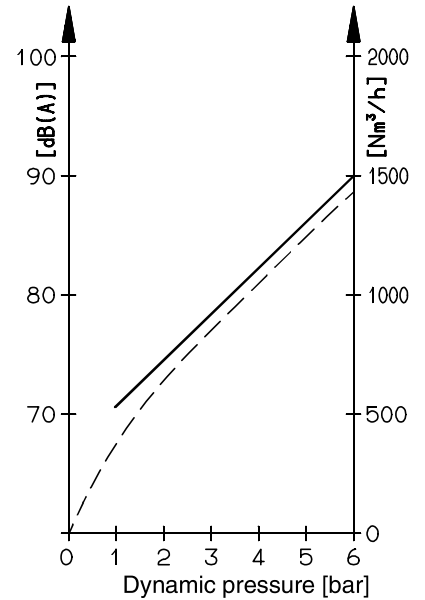


Silencer G 1 1/4

Cat. No. 0011230

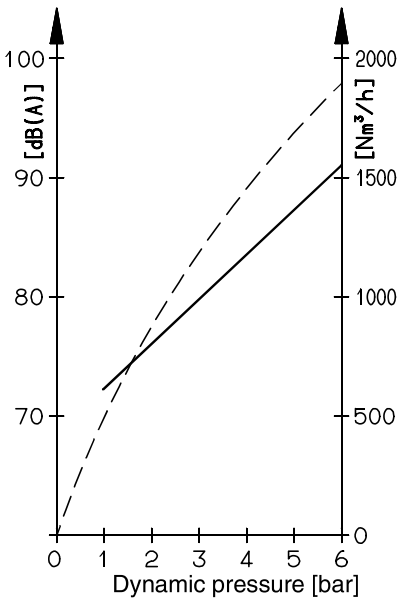

Silencer G 1 1/2

Cat. No. 0016630

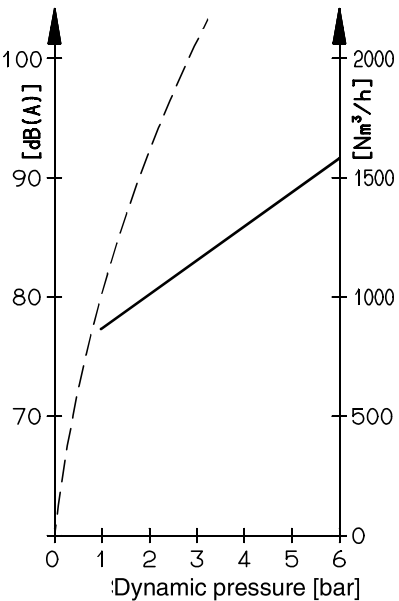

Silencer G 2

Cat. No. 0016730

